

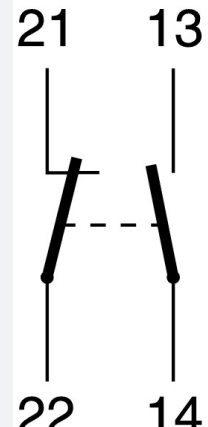


**Auxiliary contact, for PLS, postal Code, PKNM, ZP-A40...-
ASA...IHK...WHK, Z-MS, 1N/O+1N/C, 0.5HP**

Part no. ZP-IHK
Catalog No. 286052

EL-Nummer 1609488
(Norway)

Delivery program

| | | |
|----------------------------|--|---|
| Basic function | | Accessories for combined residual-current/power circuit-breakers Accessories for miniature circuit-breaker |
| Basic function accessories | | Auxiliary contacts |
| Application | | Switchgear for industrial and advanced commercial applications |
| Product range | | Accessory |
| Side mounting | | for fitting on left to: LS, FI/LS |
| Contact sequence | |  |

Technical data

Design verification as per IEC/EN 61439

| | | |
|--|----|----|
| Technical data for design verification | | |
| Operating ambient temperature min. | °C | -5 |
| Operating ambient temperature max. | °C | 40 |

Technical data ETIM 7.0

| | | |
|---|---|------------------|
| Devices for distribution board-/surface mounting (EG000062) / Auxiliary device for distribution board devices (EC001286) | | |
| Electric engineering, automation, process control engineering / Electrical installation, device / Breaker switch component / Auxiliary contact unit for distribution board (ec@ss10.0.1-27-14-35-02 [AKE327013]) | | |
| Device fitting | | Universal |
| Additional equipment | | Auxiliary switch |
| Attached at delivery | | No |
| Assembly width (TE) | | 0.5 |
| Number of contacts as normally open contact | | 1 |
| Number of contacts as normally closed contact | | 1 |
| Number of contacts as change-over contact | | 0 |
| Number of fault-signal switches | | 0 |
| Rated switch current | A | 3 |
| Rated voltage | V | 230 |
| Voltage type for actuating | | AC |
| With auto test for earth leakage function | | No |

Suitable for max. number of poles main contact unit (total)

2

Suitable for max. current main contact unit

A

6

Dimensions

